

THE FUTURE IS ON®

LEVITON®



Entertainment Applications

LINE CARD



ENTERTAINMENT APPLICATIONS

Rough Service Devices

Rhino-Hide® Single Pole Devices

- Designed for easy assembly and disassembly without special tools
- Insulating sleeves are color-coded for phase identification and designed for rugged applications
- Available in 15 (to 150 A/600 V), 16/18 (to 400 A/600 V), 17/22/23 (to 690 A/600 V) and 49 (to 1135 A/1000 V) Series devices in a variety of termination styles and cord ranges



Locking Devices

Black & White® Extra Heavy-Duty Plugs & Connectors

- Designed for fast assembly
- Durable nylon housing features wider ribs for better grip
- Backed by a limited lifetime warranty
- Available in a variety of configurations (15, 20 and 30 Amp, 125 to 600 Volt, NEMA and Non-NEMA)



V-0-Max® Industrial Grade Flush Receptacles

- Flammability rated V-0 per UL 94
- Fast and secure installations with triple head brass #10 terminal screws
- Valox® construction resists impact and abuse
- Available in a variety of configurations (15, 20 and 30 Amp, 125 to 600 Volt, NEMA and Non-NEMA)
- Color coding indicates voltage rating



Straight Blade Devices

Plugs, Connectors & Receptacles

- Tamper-resistant, weather-resistant, corrosion-resistant, illuminated, power indication, surge protective, and isolated ground versions
- Available in a variety of configurations (15, 20, 30, 50 and 60 Amp, 125 to 600 Volt, NEMA and Non-NEMA)



ALL CATEGORIES FEATURED ON THIS PAGE ARE UL/FED SPEC/CSA/NOM-ANCE

Ground Fault Circuit Interrupters (GFCIs)

Self-Test GFCI Receptacles

Extra-Heavy Duty Industrial & Hospital Grade

- Protect from hazards of electric shock and electrocution
- Patented SmartlockPro® protection detects and prevents against line-load reversal miswiring, and prevents resetting when ground fault protection has been lost
- Fed Spec rated for the most demanding environments



Portable GFCI Devices

- Rainproof and outdoor rated
- Fully comply with NEC & OSHA regulations for construction sites
- Auto & manual reset versions available



Watertight Devices

IEC 60309 Pin & Sleeve Devices

LEV Series North American configurations

- Plugs, Connectors, Receptacles, Inlets, & Mechanical Interlocks in 30 and 60 Amp
- Several features simplify and speed assembly
- Superior watertight ratings for use in any environment - IP66, IP67, IP68, and IP69K rated
- Improved safety and productivity with Inform™ technology
 - Plugs and connectors with local power indication
 - Mechanical interlocks with local and remote monitoring
- Industry-leading 5-year warranty



 inform™

International Configurations

- Plugs, connectors, receptacles and inlets in 16, 32, 63, and 125 Amp



Wetguard® Watertight Devices

Straight Blade & Locking Plugs, Connectors, Receptacles & Inlets

- High-visibility yellow for safety
- IEC IP66 & IP67, NEMA 3, 3S, 4, 4X, 6 & 6P enclosure ratings
- Plugs & connectors are IP69K rated when caps are attached
- Available in a variety of configurations (15, 20, and 30 Amp, 125 to 600 Volt, Single- and three-phase)

WATERTIGHT RATINGS FOR WETGUARD & LEV SERIES DEVICES ARE SECOND TO NONE!

ENTERTAINMENT APPLICATIONS

Wire Mesh Safety Grips

Pulling Grips

- For pulling a variety of conductors, cables and rope
- Galvanized steel for greater strength and longer life

Strain Relief Grips


- Connect cable or flexible conduit to electrical enclosures and equipment
- Nylon body and mesh or aluminum body with stainless steel mesh

Support Grips

- Holds the weight of cable on vertical or sloping runs
- Tinned bronze or stainless steel wire mesh



Portable Outlet Boxes

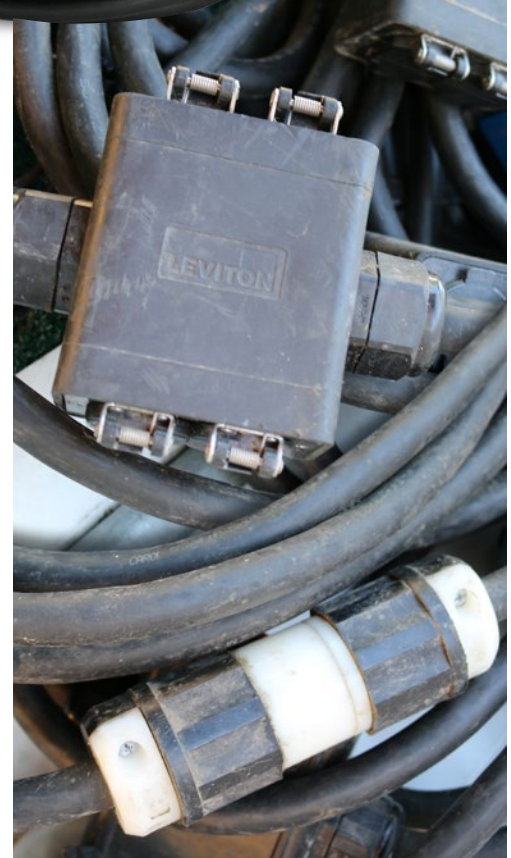

Industrial Grade Portable Outlet Boxes

- Made from a high-performance, UL listed TPV for durability and safety
- Pendant and feed-thru styles; in single- and two-gang configurations
- Available in high-visibility yellow or black

Cover Plates

- Durable polycarbonate construction provides exceptional impact resistance and service life
- Multiple configurations for a wide variety of wiring device combinations
- Weather-resistant flip-lid versions provide NEMA 3R protection while not in use

Visit our Website at:
leviton.com/entertainment
email: industrial@leviton.com

Leviton Manufacturing Co., Inc.
201 N Service Rd, Melville, NY 11747
Telephone: 1-800-323-8920 • FAX: 1-800-832-9538
Tech Line: 1-800-824-3005 (M-F 8AM-10PM; Sat 9AM-7PM; Sun 9AM-5PM)
© 2024 Leviton Manufacturing Co., Inc. All rights reserved. Q-920A 011624