



THE FUTURE IS ON®

LEVITON®



Manufacturing Industry Solutions

LINE CARD

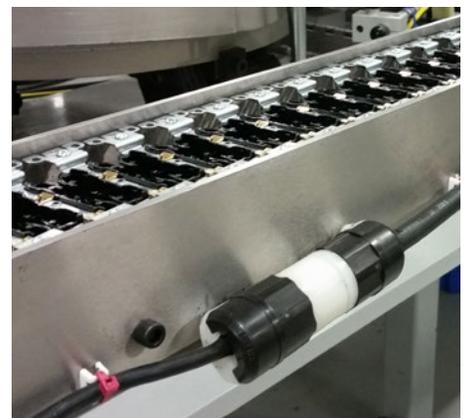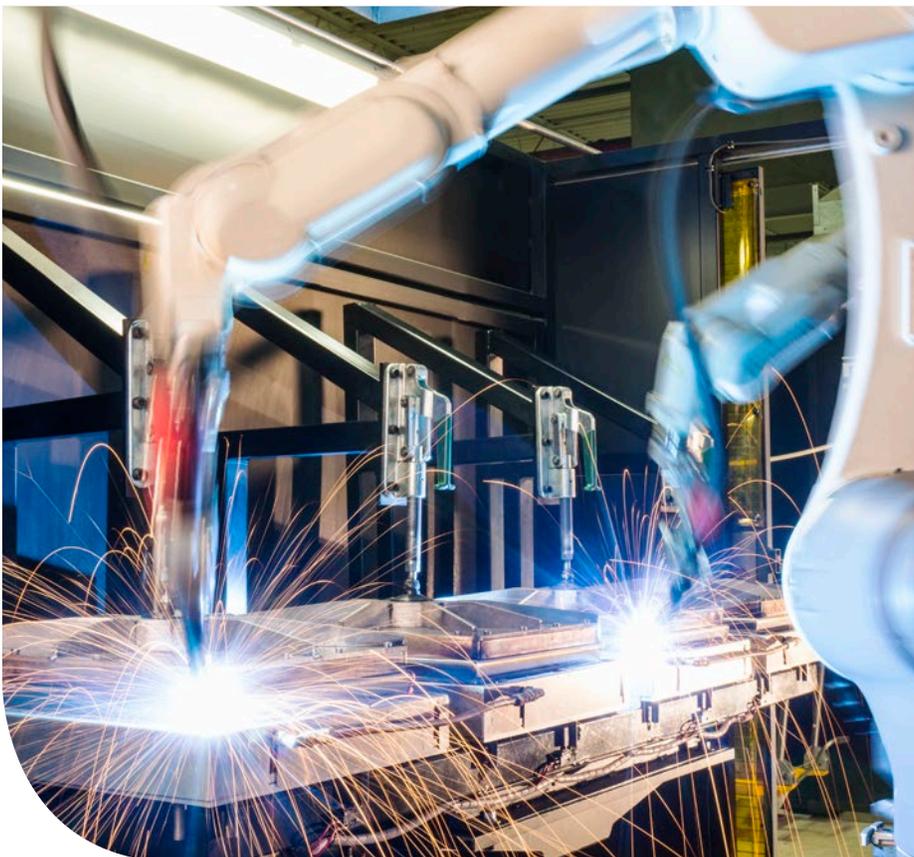

MANUFACTURING INDUSTRY SOLUTIONS

Wetguard® Watertight Devices

- 15-30 A, 125-600 V
- Full complement of device types: plugs, connectors, inlets, outlets, PVC and Stainless Steel FD boxes, covers, and other accessories
- Industry leading lifetime warranty
- IP66, IP67 and NEMA 4, 4X, 6, 6P; Plugs & connectors rated IP69K (when mated with covers)
- Available in black or yellow



Rhino-Hide® Rough Service Devices

- 15-20 A, 125-250 V
- Straight blade and locking plugs, connectors and receptacles
- IP66, IP67, IP68, IP69K and NEMA 3R, 4, 4X, 6, 6P, 12, 13
- Industry leading lifetime warranty



LEV Series IEC 60309 Pin & Sleeve Devices

- Industrial grade plugs, connectors, receptacles, inlets and mechanical interlocks
- 20, 30, 60 and 100 A North American Configurations
- IP66, IP67, IP68 and IP69K Rated
- Superior watertight ratings for use in any environment
- Improved safety and productivity with Inform™ Technology



Powerswitch® Safety Disconnect Switches

- 30, 60 and 100 A, Fused & Non-Fused in Non-Metallic Enclosures
- 30, 60, 80 and 100 A, Non-Fused in Stainless Steel Enclosures
- Curve- and Slope-top versions; Inform™ Technology also available
- IP69K for high pressure, high temperature washdown
- NSF Certified for hygiene requirements



Powerswitch® Manual Motor Controllers

- Toggle switches, enclosed switches, and enclosure options available
- AC Control for Single-Phase or Three-Phase Motor Loads
- 30, 40, 60 A, 120-600 VAC
- UL 508 listed "Suitable as Motor Disconnect" (30 A & 40 A)
- Max HP Rating: 30HP 600 VAC
- Available with metallic or non-metallic Type 1, 3R or 4X enclosures



Portable GFCIs

- 15 and 20 A, 120 V
- Compact right angle plugs available in NEMA 5-15 and 5-20 configurations
- Rainproof, outdoor rated GFCI module
- Complies with NEC and OSHA regulations for construction sites
- Automatic and manual reset versions



Wire Mesh Safety Grips

- Pulling grips: galvanized steel, flexible and rotating eye attachments available
- Strain-relief grips: galvanized steel, stainless steel or nylon wire, liquid-tight and dust-tight versions available
- Support grips: tinned bronze, stainless steel or galvanized steel, wide variety of styles



Portable Outlet Boxes and Covers

- Single- and two-gang, feed-thru and pendant style boxes
- Many cover configurations; flip-lid versions are rated NEMA Type 3R
- Resistant to heat, harsh chemicals and impacts



Black & White® Extra Heavy-Duty Plugs & Connectors

- 15-50 A, 125-600 V
- NEMA and Non-NEMA configurations
- UL/Fed.Spec./CSA/NOM
- Solid brass blades and contacts
- Corrosion-resistant and power indication versions available



V-0-MAX® Locking Receptacles

- 15-30 A, 125-600 V
- NEMA and Non-NEMA configurations
- UL/Fed. Spec./CSA/NOM
- UL V-0 flammability rating
- Nickel-plated brass strap and clamp type terminals



Visit our Website at:

leviton.com/manufacturing

email: industrial@leviton.com

Q-1170A

011724

Leviton Manufacturing Co., Inc.

201 N Service Rd, Melville, NY 11747

Telephone: 1-800-323-8920 • FAX: 1-800-832-9538

Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): 1-800-824-3005

© 2024 Leviton Manufacturing Co., Inc. All rights reserved.