

Meeting Additional Power Needs in Health Care Facilities



Hospital Grade 4-in-1 Receptacles provide a simple transition in retrofit applications to comply with new receptacle requirements in health care facilities. These devices allow you to increase the number of receptacles in your facility without having to pull new wires.

Both the NFPA 99 and the National Electrical Code have applied new patient care room definitions for the minimum number of receptacles required:

NFPA 99, 2024 Edition, 6.3.2.2.2 Minimum Number of Receptacles – “The number of receptacles shall be determined by the intended use of the spaces in accordance with...”

- **Receptacles for Patient Bed Locations in General Care Areas (Category 2).** Each patient bed location shall be provided with a minimum of **8** receptacles.
- **Receptacles for Patient Bed Locations in Critical Care Areas other than Operating Rooms (Category 1).** Each patient bed location shall be provided with a minimum of **14** receptacles.
- **Receptacles for Operating Rooms.** Operating rooms shall be provided with a minimum of **36** receptacles.

NEC/NFPA 70, as of 2014 Edition, Article 517.18(B) – “Each patient bed location shall be provided with a minimum of eight receptacles... They shall be permitted to be of the single, duplex, or **quadruplex type** or any combination of the three.

All receptacles shall be listed ‘hospital grade’ and shall be so identified.”



Features:


- Surge Protective and Isolated Ground versions available
- Terminal Wiring Screws fit Inside a Standard Single Gang, 4" Octagon, and 4" Square Wall Box
- Termination anchor holes for easy conductor wiring
- Easy-to-read voltage and amperage rating molded onto face
- Impact and chemical resistant nylon cover and base

Ordering Information

HOSPITAL GRADE			
Description		15A	20A
4-in-1 Receptacles	White	1254-HW	21254-HW
	Ivory	1254-HI	21254-HI
	Gray	—	21254-HGY
	Brown	1254-H	21254-H
	Red	1254-HR	21254-HR
4-in-1 Receptacles, Isolated Ground	Orange	1254-IG	21254-IG
	White	—	21254-IGW
	Ivory	—	21254-IGI
4-in-1 Receptacles, Surge Protective	White	8480-W	8490-W
	Ivory	8480-I	8490-I
	Red	8480-R	8490-R
4-in-1 Receptacles, Surge Protective, Isolated Ground	Orange	—	8490-IG
	White	8480-IGW	—
	Ivory	8480-IGI	8490-IGI
	Blue	8480-IGB	8490-IGB


Dimensions

4-in-1 Receptacles

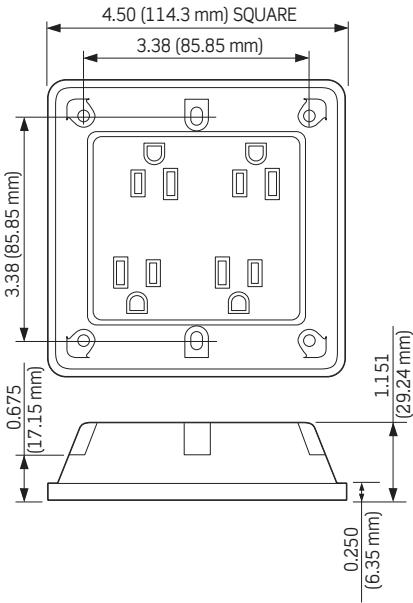


Back View

(21254-HI Shown, all units are hardwired)

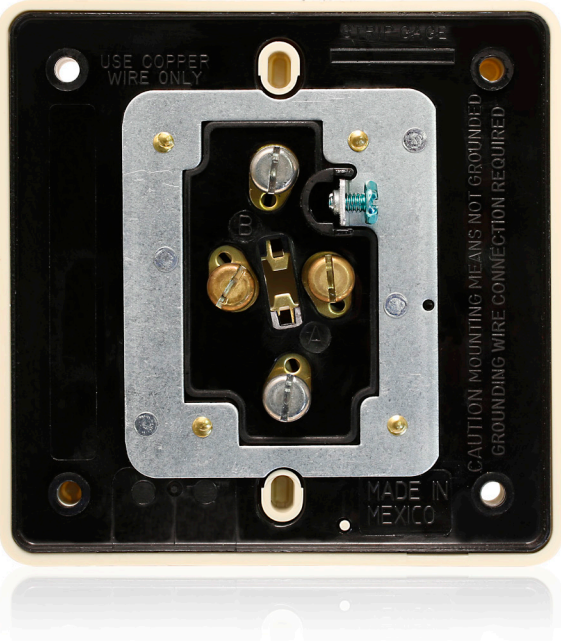

Mounting Options

Compatible with Single Gang Boxes, Single Gang Plaster Rings, and 4" Square, Octagon or Ring Boxes

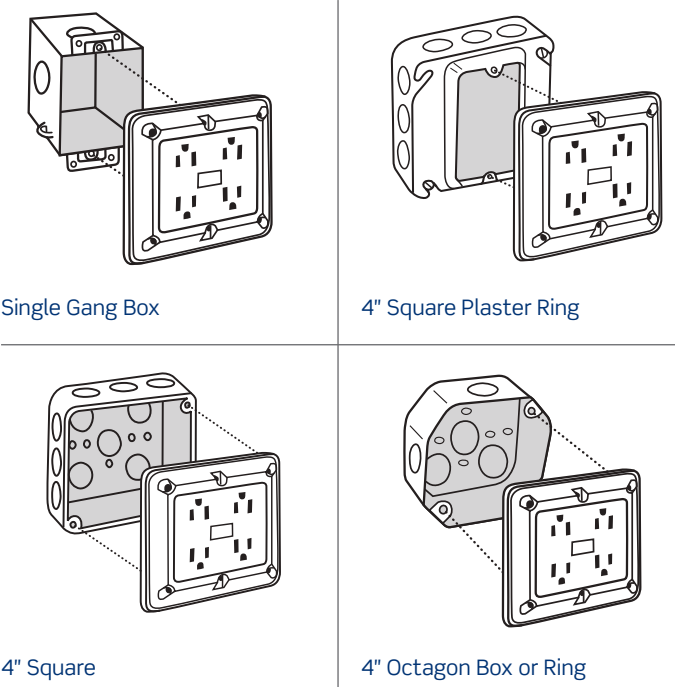

Visit our Website at:

www.leviton.com/healthcare

email: commercial@leviton.com

Q-919A

Leviton Manufacturing Co., Inc.

201 N Service Rd, Melville, NY 11747

Telephone: 1-800-323-8920 • FAX: 1-800-832-9538

Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): 1-800-824-3005

© 2024 Leviton Manufacturing Co., Inc. All rights reserved.

052224