

Power Distribution

Power that drives your network





Servers, storage, and networking equipment only perform as well as the power that drives them. Leviton Power Distribution Units (PDUs) provide robust, reliable power to rack and cabinet applications.

Choose from a wide variety of horizontal and vertical models, or rack-mounted units with surge protection.



P1000 Series PDUs

Leviton P1000 Series PDUs are ideal for server rooms and other environments that require cost-effective “always on” power. The robust, compact design makes them a perfect fit for harsh environments where space is limited.



5500/5505 Series PDUs


Leviton 5500 and 5505 Series PDUs help power and protect vital electronic equipment. These PDUs provide Surge Protection for connected equipment and are Listed to UL 1449.




P1000 Series PDUs



Input Plug Types

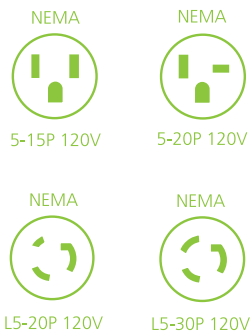

Output Receptacle Types

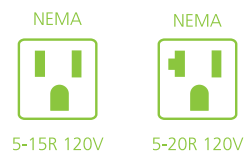

Leviton P1000 Series PDUs are designed for data centers, wiring closets, and other environments that require cost-effective, “always on” power. The robust, compact design ensures that these products can be used wherever reliability and density are important.


- All models feature circuit breaker protection to prevent current overloads
- Available in 120V configurations with 15, 20, or 30 amps
- LED indicators for power and grounding/polarity
- Hardwired power input cord
- 18-gauge cold-rolled steel construction
- Available in vertical Zero-U or horizontal 19-inch rack-mount styles



P1000 Series PDUs



P1021-12S

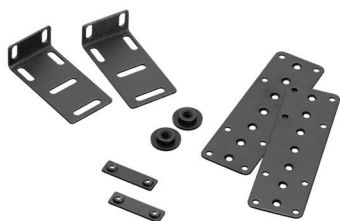

Vertical P1000 units ship with flat brackets, L-brackets, backplates, mounting buttons, screws, and washers to support a variety of rack and cabinet mounting options.



P1041-10S

P1044-10L

UNMETERED HORIZONTAL POWER DISTRIBUTION UNITS (PDUs), SINGLE INPUT

PART NO.	INPUT				OUTPUT			DIMENSIONS (inches) H x W x D
	VOLTAGE	AMPS	CORD LENGTH	PLUG TYPE	VOLTAGE	RECEPTACLE TYPE	RECEPTACLE QUANTITY	
P1020-12S	120V	15A	12'	5-15P	120V	5-15R	10	1.75 x 19 x 4.5
P1021-12S	120V	20A	12'	5-20P	120V	5-20R	10	1.75 x 19 x 4.5
P1022-12L	120V	20A	12'	L5-20P	120V	5-20R	10	1.75 x 19 x 4.5
P1023-12L	120V	30A	12'	L5-30P	120V	5-20R	16	3.5 x 19 x 4.5


UNMETERED VERTICAL POWER DISTRIBUTION UNITS (PDUs), SINGLE INPUT

PART NO.	INPUT				OUTPUT			DIMENSIONS (inches) L x W x D
	VOLTAGE	AMPS	CORD LENGTH	PLUG TYPE	VOLTAGE	RECEPTACLE TYPE	RECEPTACLE QUANTITY	
P1040-10S	120V	15A	10'	5-15P	120V	5-15R	16	30 L x 1.8 W x 1.75
P1041-10S	120V	20A	10'	5-20P	120V	5-20R	16	30 L x 1.8 W x 1.75
P1042-10L	120V	20A	10'	L5-20P	120V	5-20R	16	30 L x 1.8 W x 1.75
P1043-10S	120V	20A	10'	5-20P	120V	5-20R	24	48 L x 1.8 W x 1.75
P1044-10L	120V	20A	10'	L5-20P	120V	5-20R	24	48 L x 1.8 W x 1.75
P1045-10L	120V	30A	10'	L5-30P	120V	5-20R	24	48 L x 1.8 W x 1.75


All P1000 Series PDUs have hard-wired input cords.

5500 / 5505 Series PDUs

Input Plug Types

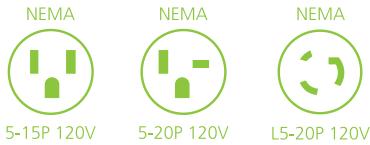

Output Receptacle Types

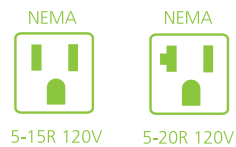

Leviton 5500 and 5505 Series Surge Protected Power Distribution Units (PDUs) help power and protect vital electronic equipment. The 5500 and 5505 Series share several key features, including:

- Resettable circuit breaker to protect against overloading
- 12 receptacles: 10 in back, 2 in front
- 20-amp versions available with either straight blade or locking input plug
- Mounts horizontally on 19-inch racks or cabinets
- UL Listed: UL 1449 and 1363

5500 Series with Enhanced Surge Protection

- **Peak surge current:** 72 kA
- **VPR — L-N:** 400 Vpk, L-G/N-G: 500 Vpk
- **EMI/RFI noise filtering:** 100 kHz to 30 MHz, -10 dB to -35 dB
- **Type SPD:** 3CA
- **Physical dimensions:** 1.75" H x 19" W x 4.55" D

5505 Series with Surge Protection

- **Peak surge current:** 27 kA
- **VPR — L-N:** 600 Vpk, L-G/N-G: 700 Vpk
- **EMI/RFI noise filtering:** 100 kHz to 30 MHz, -5 dB to -40 dB
- **Type SPD:** 3CA
- **Physical dimensions:** 1.75" H x 19" W x 2.5" D

5500 / 5505 Series PDUs



5500-190



5500-20L

5500 SERIES POWER DISTRIBUTION UNITS (PDUS) WITH SURGE PROTECTION

PART NO.	FOOTPRINT	ON/OFF SWITCH		INPUT			OUTPUT			DIMENSIONS (inches) L x W x D	
		YES	NO	INPUT VOLTAGE	AMPS	CORD LENGTH	INPUT PLUG	OUTPUT VOLTAGE	RECEPTACLE TYPE		RECEPTACLE QUANTITY
5500-190	Horizontal / Rack Mnt.	•		120V	15A	12'	5-15P	120V	5-15R	12	1.75 x 19 x 4.55
5500-192	Horizontal / Rack Mnt.	•		120V	20A	12'	5-20P	120V	5-20R	12	1.75 x 19 x 4.55
5500-20L	Horizontal / Rack Mnt.	•		120V	20A	12'	L5-20P	120V	5-20R	12	1.75 x 19 x 4.55
5500-15N	Horizontal / Rack Mnt.		•	120V	15A	12'	5-15P	120V	5-15R	12	1.75 x 19 x 4.55

5505 SERIES POWER DISTRIBUTION UNITS (PDUS) WITH SURGE PROTECTION

5505-190	Horizontal / Rack Mnt.	•		120V	15A	12'	5-15P	120V	5-15R	12	1.75 x 19 x 2.5
----------	------------------------	---	--	------	-----	-----	-------	------	-------	----	-----------------

All 5500/5505 Series PDUs have hard-wired Input Cords.

Today's networks must be fast and reliable, with the flexibility to handle ever-increasing data demands. Leviton can help expand your network possibilities and prepare you for the future. Our end-to-end cabling systems feature robust construction that reduces downtime, and performance that exceeds standards. We offer quick-ship make-to-order solutions from our US and UK factories. We even invent new products for customers when the product they need is not available. All of this adds up to the **highest return on infrastructure investment.**

USA — NETWORK SOLUTIONS HEADQUARTERS

2222 - 222nd Street S.E., Bothell, WA, 98021, USA
+1 (800) 722 2082 | infoUSA@leviton.com | Leviton.com/NS

Customer Service

+1 (800) 722 2082
insidesales@leviton.com

International Customer Service

+1 (800) 722 2082 (Option 1)
intl@leviton.com

Leviton Cable

(formerly Berk-Tek)
+1 (800) 237 5835
infoUSA@leviton.com

Technical Support

+1 (800) 722 2082
appeng@leviton.com

APAC

+85 (2) 3620 2602 | infoAPAC@leviton.com | Leviton.com/NS

Customer Service

+1 (631) 812 6228
infoASEAN@leviton.com

China

+85 (2) 2774 9876
infoChina@leviton.com

South Korea

+82 (2) 3273 9963
infoKorea@leviton.com

CANADA

+1 (800) 461 2002 | infoCanada@leviton.com | Leviton.com/NS

Customer Service

+1 (514) 954 1840
pcservice@leviton.com

Network Solutions products are **available worldwide in over 100 countries.** Visit us online at leviton.com/ns to learn more.



© Copyright Leviton Manufacturing Co., Inc.

EUROPE

Viewfield Industrial Estate, Glenrothes, KY6 2RS, UK
+44 (0) 1592 772124 | infoEurope@leviton.com | Leviton.com/NS/EMEA

Customer Service

+44 (0) 1592 772124
customerserviceEU@leviton.com

Technical Support

+44 (0) 1592 778494
appeng.EU@leviton.com

Benelux

+44 (0) 1592 772124
infoBenelux@leviton.com

Nordics

+46 (70) 9675033
infoNordics@leviton.com

Central & Eastern Europe (CEE)

+44 (0) 1592 772124
infoCEE@leviton.com

Portugal

+351 (21) 421 4133
infoPortugal@leviton.com

DACH

+49 (0) 173 272 0128
infoDACH@leviton.com

Spain

+34 (91) 490 59 19
infoSpain@leviton.com

France

+33 (0) 1709 87826
infoFrance@leviton.com

UK & Ireland

+44 (0) 1592 772124
infoUK@leviton.com

Italy

+39 (02) 3534896 (Milan)
+39 (06) 68584613 (Rome)
infoitaly@leviton.com

LATAM

infoLATAM@leviton.com | Leviton.com/NS

Customer Service

+52 (55) 2333 5963
infoLATAM@leviton.com

Caribbean

+1 (954) 593 1896
infoCaribbean@leviton.com

Mexico

+52 (55) 2128 6286
lsamarketing@leviton.com

Colombia

+57 (1) 743 6045
infoColombia@leviton.com

MIDDLE EAST & AFRICA

Bay Square, Building 3, Office 205, Business Bay, Dubai, UAE
+971 (4) 247 9800 | infoMEA@leviton.com | Leviton.com/NS

Customer Service

+971 (4) 247 9800
lmeinfo@leviton.com