



Residential Lighting Controls

Lighting Controls
for Every Home



From Traditional to Smart and everything in between!

Leviton introduced our first Decora Switch in the early 70's and has been making best-in-class dimmers at the forefront of changing lighting technology ever since. Leviton dimmers provide a smooth full range dimming experience, employing the latest in dimming technology, features, and proven LED compatibility. Our lighting control's portfolio offers a wide range of solutions across product families to meet the needs of any room and home.



Lighting Controls | Product Families

From traditional, to smart, and everything in between



Rotary 4



Toggle Slide 5



SureSlide 6



Decora Slide 7




Decora Digital 8



Decora Smart 9



Decora Sensors 14

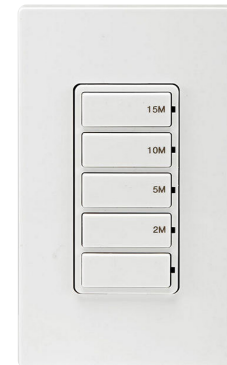

Decora Timers 16



Illumatech 18

ROTARY

Leviton's Rotary Family

- The classic design of Rotary dimmers and fan controls provide a familiar intuitive control with a traditional look commonly used in retrofit applications
- Rotary dimmers are entry level, affordable, and work with existing wiring - no neutral wire required



Catalog Number	Description	Dimming Type	Ratings	Voltage (VAC, Hz)	Replaces	Wired 3-Way*	Neutral Required	Color Options
RNL06-10Z	Rotary ON/OFF Electro-Mechanical Rotary Dimmer - White/ Ivory/ Light Almond	Forward Phase TRIAC	150W LED/CFL, 600W Inc	120V, 60 Hz	N/A	N	N	Y
RDL06-10Z	Rotary Push ON/Push OFF Electro-Mechanical Rotary Dimmer - White/ Ivory/ Light Almond	Forward Phase TRIAC	150W LED/CFL, 600W Inc	120V, 60 Hz	N/A	Y	N	Y
6616-1XW	Rotary Fan Speed Control - White	N/A	5 Amp	120V, 60 Hz	N/A	N	N	Y
6616-1XI	Rotary Fan Speed Control - Ivory	N/A	5 Amp	120V, 60 Hz	N/A	N	N	Y
6639-10Z	Rotary Quiet Fan Speed Control - White/ Ivory/ Light Almond	N/A	1.5 Amp	120V, 60 Hz	N/A	N	N	N

*Standard 3-way switch

Accessories



Catalog Number	Description
26115-W	Knob for Rotary Devices - White
26115-I	Knob for Rotary Devices - Ivory
26115-T	Knob for Rotary Devices - Light Almond
26115-E	Knob for Rotary Devices - Black

Leviton's Toggle Slide Family

- Designed to replace or match traditional style toggle switches while offering quality LED dimming performance
- Slim profile for easy installation in retrofit and renovation applications with no neutral required
- Automatically returns to its pre-selected light level
- Cost effective solution that works with existing traditional wallplates



Catalog Number	Description		Dimming Type	Ratings	Voltage (VAC, Hz)	Replaces	Wired 3-Way*	Neutral Required	Color Options
TSL01-10W	Toggle Slide Dimmer - White		LED Advanced - Forward Phase MOSFET	150W LED/CFL/Inc/ Halogen	120V, 60 Hz	TSL06-1LW	Y	N	N
TSL01-00I	Toggle Slide Dimmer - Ivory		LED Advanced - Forward Phase MOSFET	150W LED/CFL/Inc/ Halogen	120V, 60 Hz	TSL06-1LI	Y	N	N
TSL01-00T	Toggle Slide Dimmer - Light Almond		LED Advanced - Forward Phase MOSFET	150W LED/CFL/Inc/ Halogen	120V, 60 Hz	TSL06-1LT	Y	N	N
TSL01-10G	Toggle Slide Dimmer - Gray		LED Advanced - Forward Phase MOSFET	150W LED/CFL/Inc/ Halogen	120V, 60 Hz	TSL06-1LG	Y	N	N
TSL01-10E	Toggle Slide Dimmer - Black		LED Advanced - Forward Phase MOSFET	150W LED/CFL/Inc/ Halogen	120V, 60 Hz	TSL06-1LE	Y	N	N
TSL01-10B	Toggle Slide Dimmer - Brown		LED Advanced - Forward Phase MOSFET	150W LED/CFL/Inc/ Halogen	120V, 60 Hz	TSL06-1LB	Y	N	N
TSM10-1LW	Toggle Slide MLV Dimmer - White		Forward Phase TRIAC	1000VA MLV, 400W LED/CFL, 1000W Inc.	120V, 60 Hz	N/A	Y	N	N
TSM10-1LI	Toggle Slide MLV Dimmer - Ivory		Forward Phase TRIAC	1000VA MLV, 400W LED/CFL, 1000W Inc.	120V, 60 Hz	N/A	Y	N	N
TSM10-1LT	Toggle Slide MLV Dimmer - Light Almond		Forward Phase TRIAC	1000VA MLV, 400W LED/CFL, 1000W Inc.	120V, 60 Hz	N/A	Y	N	N
TSF01-10W	Quiet Toggle Slide Fan Speed Control - White		N/A	1.5 Amp	120V, 60 Hz	N/A	Y	N	N

*Standard 3-way switch

Leviton's SureSlide Family

- Reliable cost-effective dimming, ideal for meeting code applications such as CA Title 24 and IECC
- Product family includes 2-Wire and 3-Wire (with neutral) options for both retrofit and new construction applications
- Simple slide bar interface with adjustable settings for LED dimming performance
- Slim profile of <1" for easy installation



Catalog Number	Description	Dimming Type	Ratings	Voltage (VAC, Hz)	Replaces	Wired 3-Way*	Neutral Required	Color Options
6672-1LW	SureSlide Dimmer - White	Forward Phase TRIAC	150W LED/CFL, 600W Inc	120V, 60 Hz	N/A	N	N	N
6672-1LI	SureSlide Dimmer - Ivory	Forward Phase TRIAC	150W LED/CFL, 600W Inc	120V, 60 Hz	N/A	N	N	N
6672-1LT	SureSlide Dimmer - Light Almond	Forward Phase TRIAC	150W LED/CFL, 600W Inc	120V, 60 Hz	N/A	N	N	N
6674N-10W	SureSlide Preset Dimmer - White	Forward Phase TRIAC	150W LED/CFL, 300W Inc	120V, 60 Hz	N/A	Y	Y	N
66741-10W	SureSlide Preset Dimmer - White 	LED Advanced - Forward Phase MOSFET	150W LED/CFL/Inc/ Halogen	120V, 60 Hz	6674-10W	Y	N	N
66741-00I	SureSlide Preset Dimmer - Ivory 	LED Advanced - Forward Phase MOSFET	150W LED/CFL/Inc/ Halogen	120V, 60 Hz	6674-P0I	Y	N	N
66741-00T	SureSlide Preset Dimmer - Light Almond 	LED Advanced - Forward Phase MOSFET	150W LED/CFL/Inc/ Halogen	120V, 60 Hz	6674-P0T	Y	N	N
66741-00E	SureSlide Preset Dimmer - Black 	LED Advanced - Forward Phase MOSFET	150W LED/CFL/Inc/ Halogen	120V, 60 Hz	6674-P0E	Y	N	N
66741-00B	SureSlide Preset Dimmer - Brown 	LED Advanced - Forward Phase MOSFET	150W LED/CFL/Inc/ Halogen	120V, 60 Hz	6674-P0B	Y	N	N
66EV-10W	SureSlide ELV Dimmer - White	Reverse Phase MOSFET	300W ELV	120V, 60 Hz	N/A	Y	Y	N
66EV-10I	SureSlide ELV Dimmer - Ivory	Reverse Phase MOSFET	300W ELV	120V, 60 Hz	N/A	Y	Y	N
66EV-10T	SureSlide ELV Dimmer - Light Almond	Reverse Phase MOSFET	300W ELV	120V, 60 Hz	N/A	Y	Y	N
661F-10W	SureSlide Quiet Fan 3 Speed Control - White	N/A	1.5A Ceiling Fan	120V, 60 Hz	N/A	Y	N	N
661F-10I	SureSlide Quiet Fan 3 Speed Control - Ivory	N/A	1.5A Ceiling Fan	120V, 60 Hz	N/A	Y	N	N
661F-10T	SureSlide Quiet Fan 3 Speed Control - Light Almond	N/A	1.5A Ceiling Fan	120V, 60 Hz	N/A	Y	N	N
66DF-10W	SureSlide Dual Quiet Fan/Light Control - White	Forward Phase TRIAC	150W LED/CFL, 300W Inc Light, 1.5A Fan	120V, 60 Hz	N/A	N	N	N
66DF-10I	SureSlide Dual Quiet Fan/Light Control - Ivory	Forward Phase TRIAC	150W LED/CFL, 300W Inc Light, 1.5A Fan	120V, 60 Hz	N/A	N	N	N
66DF-10T	SureSlide Dual Quiet Fan/Light Control - Light Almond	Forward Phase TRIAC	150W LED/CFL, 300W Inc Light, 1.5A Fan	120V, 60 Hz	N/A	N	N	N

*Standard 3-way switch

Leviton's Decora Slide Family

- Classic rocker style dimmers with a vertical slide bar are a preferred aesthetic to modernize the home and transform a room
- Provides an elegant upgrade that works with existing wiring in newer and older homes, no neutral required
- Flicker-free dimming performance with optional settings to personalize lighting such as dimming range adjustment and a locator LED to easily find the dimmer in the dark
- Color change faceplates to match any décor



Catalog Number	Description	Dimming Type	Ratings	Voltage (VAC, Hz)	Replaces	Wired 3-Way*	Neutral Required	Color Options
DSL01-1LW	Decora Slide Dimmer - White 	LED Advanced - Forward Phase MOSFET	150W LED/CFL/Inc/Halogen	120V, 60 Hz	DSL06-1LZ	Y	N	Y**
DSL01-1LI	Decora Slide Dimmer - Ivory 	LED Advanced - Forward Phase MOSFET	150W LED/CFL/Inc/Halogen	120V, 60 Hz	DSL06-1LZ	Y	N	Y**
DSL01-1LT	Decora Slide Dimmer - Light Almond 	LED Advanced - Forward Phase MOSFET	150W LED/CFL/Inc/Halogen	120V, 60 Hz	DSL06-1LZ	Y	N	Y**
ESL01	Decora Lever Edge Rocker Slide Dimmer - White	Forward Phase MOSFET	150W LED/CFL/Inc/Halogen	120V, 60 Hz	N/A	Y	N	Y**
DSE06	Decora Slide ELV Dimmer - W/I/LA	Reverse Phase MOSFET	600VA ELV, 300W LED/CFL. 600 Inc	120V, 60 Hz	N/A	Y	Y	Y***
DS710	Decora Slide 0-10V Dimmer - W/I/LA	0-10V	1200VA-120VAC, 1500VA-277VAC, 50mA DC max sink current for 0-10V control	120/277V, 60Hz	N/A	Y	N	Y***
DSM10	Decora Slide MLV Dimmer - W/I/LA	Forward Phase TRIAC	1000VA MLV, 450W LED/CFL, 1000W Inc.	120V, 60 Hz	N/A	Y	N	Y**
DSF01	Quiet Fan Speed Control - W/I/LA	N/A	1.5A Ceiling Fan	120V, 60 Hz	N/A	Y	N	Y***

*Standard 3-way switch

Accessories



Catalog Number	Description
LIGHTED COLOR CHANGE FACEPLATES**	
DSKIT-W	Decora Slide Color Change Faceplate - White
DSKIT-I	Decora Slide Color Change Faceplate - Ivory
DSKIT-T	Decora Slide Color Change Faceplate - Light Almond
DSKIT-B	Decora Slide Color Change Faceplate - Brown
DSKIT-E	Decora Slide Color Change Faceplate - Black
DSKIT-G	Decora Slide Color Change Faceplate - Gray
DSKIT-R	Decora Slide Color Change Faceplate - Red



Catalog Number	Description
NON LIGHTED COLOR CHANGE FACEPLATES***	
DSKIT-NW	Decora Slide Color Change Faceplate - White
DSKIT-NI	Decora Slide Color Change Faceplate - Ivory
DSKIT-NT	Decora Slide Color Change Faceplate - Light Almond
DSKIT-NB	Decora Slide Color Change Faceplate - Brown
DSKIT-NE	Decora Slide Color Change Faceplate - Black
DSKIT-NG	Decora Slide Color Change Faceplate - Gray
DSKIT-NR	Decora Slide Color Change Faceplate - Red

Leviton's Decora Digital Family

- An upgrade from slide dimmers, Decora Digital dimmers feature “tap” controls to turn lights on/off or to the desired light level
- Easily add multi-way dimming to any space to control lighting from multiple locations with wired DD00R
- Vanishing LED indication of light level and multiple color options offers a designer impact with easy installation
- Customize lighting control with dimming range adjustment (minimum dim and maximum bright), Fade Rates, or Preset Light Levels
- Color change faceplates to match any décor



Catalog Number	Description	Dimming Type	Ratings	Voltage (VAC, Hz)	Replaces	Wired 3-Way	Neutral Required	Color Options
DDL06-1LZ	Decora Digital Dimmer (no neutral)	Forward Phase TRIAC	300W LED/CFL, 600W INC	120V, 60Hz	N/A	Y	N*	Y
DDM06-1LZ	Decora Digital Dimmer	Forward Phase TRIAC	300W LED/CFL, 600W INC, 600VA MLV	120V, 60Hz	N/A	Y	Y	Y

* Requires Ground

Accessories



Catalog Number	Description	Voltage (VAC, Hz)	Neutral Required	Color Options
WIRED COMPANIONS				
DD00R-D	Wired Dimmer Companion	120/277V, 60Hz	Y	Y
DD0SR-D	Wired Switch Companion (With Locator LED)	120/277V, 60Hz	Y	Y
DD0SR-1	Wired Switch Companion (Without Locator LED)	120V, 60Hz	N	Y



Catalog Number	Description
COLOR CHANGE FACEPLATES	
DDKIT-W	Wired Dimmer Color Change Faceplate - White
DDKIT-I	Wired Dimmer Color Change Faceplate - Ivory
DDKIT-T	Wired Dimmer Color Change Faceplate - Light Almond
DDKIT-B	Wired Dimmer Color Change Faceplate - Brown
DDKIT-E	Wired Dimmer Color Change Faceplate - Black
DDKIT-G	Wired Dimmer Color Change Faceplate - Gray

Leviton's Decora Smart Family

- A feature-rich portfolio of smart lighting and load controls including dimmers, scene control, motion sensors, switches, outlets, fan controls, smart plugs, and no-neutral options
- Easily create a smart home with no hub or complex configuration - add a smart switch to porch lights so you never come home to a dark house again, use a keypad to enable scenes that adjust multiple lights at once, upgrade your bedroom to automatically turn the lights lower at night, and more
- Works with the My Leviton app and the most popular smart home platforms - no hub required
- Dimmer options to address any load type that provide a smooth full range dimming experience and proven LED compatibility with no minimum load requirement



Catalog Number	Description	Dimming Type	Ratings	Voltage (VAC, Hz)	Replaces	Wired 3-Way	Wire-free 3-Way	Neutral Required	Color Options
DIMMERS									
D36HD	Wi-Fi 3rd Gen Dimmer 	LED Advanced - Forward Phase TRIAC	300W LED/CFL, 300W INC, 300VA MLV	120V, 60Hz	D26HD	Y*	Y*	Y	Y
D26HD	Wi-Fi 2nd Gen Dimmer	Forward Phase TRIAC	300W LED/CFL, 600W INC, 600VA MLV	120V, 60Hz	DW6HD	Y*	Y*	Y	Y
D2MSD	Wi-Fi Motion Sensing Dimmer	Forward Phase TRIAC	300W LED/CFL, 450W INC, 450VA MLV	120V, 60Hz	N/A	Y*	Y*	Y	N
D2ELV	Wi-Fi ELV / LED Phase Selectable Dimmer	Forward / Reverse Phase MOSFET	300W LED/CFL, 600W INC, 600VA ELV	120V, 60Hz	N/A	Y*	Y*	Y	Y
D2710	Wi-Fi 0-10V Dimmer	0-10V	8A, 50mA DC max sink current for 0-10V control	120V / 277V, 60Hz	N/A	Y*	Y*	Y	Y
D23LP	Wi-Fi Mini Plug-In Dimmer	Forward Phase TRIAC	100W LED/CFL, 300W INC	120V, 60Hz	DW3HL	N/A	Y*	N/A	N
DN6HD	No-Neutral Dimmer	Forward Phase TRIAC	300W LED/CFL, 600W INC, 600VA MLV	120V, 60Hz	N/A	N	Y*	N	Y
SWITCHES									
D315S	Wi-Fi 3rd Gen Switch	N/A	15A General Use, 3A LED/CFL, 1/3HP Motor	120V, 60Hz	D215S	Y**	Y**	Y	Y
D215S	Wi-Fi 2nd Gen Switch	N/A	15A General Use, 5A LED/CFL, 3/4HP Motor	120V, 60Hz	DW15S	Y**	Y**	Y	Y
D215O	Wi-Fi Outdoor Plug-In Switch	N/A	15A General Use, 5A LED/CFL, 3/4HP Motor	120V, 60Hz	N/A	N/A	Y**	N/A	N
D215P	Wi-Fi Mini Plug-In Switch	N/A	15A General Use, 5A LED/CFL, 3/4HP Motor	120V, 60Hz	DW15P	N/A	Y**	N/A	N
D24SF	Wi-Fi Fan Speed Controller	N/A	1.5A Ceiling Fan	120V, 60Hz	DW4SF	Y*	Y*	Y	Y
D2SCS	Wi-Fi Scene Controller	N/A	15A General Use, 5A LED/CFL, 3/4HP Motor	120V, 60Hz	N/A	Y**	Y**	Y	Y
DN15S	No-Neutral Switch	N/A	15A General Use, 5A LED/CFL, 3/4HP Motor	120V, 60Hz	N/A	N	Y**	N	Y

*With DD00R and DD0SR
**With DD0SR

*With DAWDC and DAWSC
**With DAWSC



Catalog Number	Description	Ratings	Voltage	Enclosure	Wire-free wall-mount control	Agency
HIGH CURRENT SOLUTIONS						
D2HCS	50A High Current Switch	50A Resistive, 3HP 120VAC, 5HP 208/240VAC	120/208/240/277VAC, 60Hz	NEMA 3R Metal / Gray	Y, with DAWSC	UL916, CSA 22.2 No. 205
D2HCU	60A High Current Controller for undersized service; includes one CT pair	60A Resistive, 5HP 208/240VAC	208/240VAC, 60Hz	NEMA 3R Metal / Gray	N/A	UL3141 in the US for power control systems and load management, and CSA C22.2 No.14 in Canada



Catalog Number	Description	Dimming Type	Ratings	Voltage (VAC, Hz)	Replaces	Wired 3-Way	Wire-free 3-Way	Neutral Required	Color Options
OUTLETS									
D215R	Wi-Fi Tamper-Resistant Outlet	N/A	15A General Use, 5A LED/CFL, 3/4HP Motor	120V, 60Hz	DW15R	N/A	Y**	Y	Y
D2GF1	Wi-Fi 15A GFCI Outlet	N/A	15A, 20A Feed Through	120V, 60Hz	N/A	N/A	N	Y	N
D2GF2	Wi-Fi 20A GFCI Outlet	N/A	20A, 20A Feed Through	120V, 60Hz	N/A	N/A	N	Y	N
BRIDGES									
MLWSB	Wi-Fi Bridge	N/A	NA	120V, 60Hz	N/A	N/A	N/A	N/A	N
DNKIT	No-Neutral Dimmer + Bridge Bundle	Forward Phase TRIAC	300W LED/CFL, 600W INC, 600VA MLV	120V, 60Hz	N/A	N	Y*	N	Y

*With DAWDC and DAWSC
**With DAWSC



Catalog Number	Description	Dimming Type	Ratings	Voltage (VAC, Hz)	Replaces	Wired 3-Way	Wire-free 3-Way	Neutral Required	Color Options
DECORA SMART Z-WAVE PRODUCT FAMILY									
ZW6HD	Z-Wave 800 Series Dimmer	Forward Phase TRIAC	300W LED/CFL, 600W INC, 600VA MLV	120V, 60Hz	DZ6HD	Y*	N	Y	Y
ZW15S	Z-Wave 800 Series Switch	N/A	15A General Use, 5A LED/CFL, 3/4HP Motor	120V, 60Hz	DZ15S	Y**	N	Y	Y
ZW15R	Z-Wave 700 Series Tamper-Resistant Outlet	N/A	15A General Use, 5A LED/CFL, 3/4HP Motor	120V, 60Hz	N/A	N/A	N	Y	Y
ZW4SF	Z-Wave 700 Series Fan Speed Controller	N/A	1.5A Ceiling Fan	120V, 60Hz	N/A	Y*	N	Y	Y
DZPA1	Z-Wave 500 Series Plug-In Outlet	N/A	15A Resistive, 5A LED / CFL, 1/2HP Motor	120V, 60Hz	N/A	N/A	N	N/A	N
DZPD3	Z-Wave 500 Series Plug-In Dimmer	Forward Phase TRIAC	100W LED/CFL, 300W INC	120V, 60Hz	N/A	N/A	N	N/A	N

*With DD00R and DD0SR
**With DD0SR

Accessories



Catalog Number	Description	Voltage (VAC, Hz)	Neutral Required	Color Options
WIRED COMPANIONS				
DD00R-D	Wired Dimmer Companion	120/277V, 60Hz	Y	Y
DD0SR-D	Wired Switch Companion (With Locator LED)	120/277V, 60Hz	Y	Y
DD0SR-1	Wired Switch Companion (Without Locator LED)	120V, 60Hz	N	Y
WIRE-FREE COMPANIONS				
DAWDC	Anywhere Dimmer Companion	120V, 60Hz	N/A	N
DAWSC	Anywhere Switch Companion	120V, 60Hz	N/A	N



Catalog Number	Description
COLOR CHANGE FACEPLATES	
DDKIT-SW	Wired Switch Color Change Faceplate - White
DDKIT-SI	Wired Switch Color Change Faceplate - Ivory
DDKIT-ST	Wired Switch Color Change Faceplate - Light Almond
DDKIT-SB	Wired Switch Color Change Faceplate - Brown
DDKIT-SE	Wired Switch Color Change Faceplate - Black
DDKIT-SG	Wired Switch Color Change Faceplate - Gray



Catalog Number	Description
COLOR CHANGE FACEPLATES	
DDKIT-W	Wired Dimmer Color Change Faceplate - White
DDKIT-I	Wired Dimmer Color Change Faceplate - Ivory
DDKIT-T	Wired Dimmer Color Change Faceplate - Light Almond
DDKIT-B	Wired Dimmer Color Change Faceplate - Brown
DDKIT-E	Wired Dimmer Color Change Faceplate - Black
DDKIT-G	Wired Dimmer Color Change Faceplate - Gray



Catalog Number	Description
COLOR CHANGE FACEPLATE FOR D36HD	
D3KIT-W	Wired Dimmer Color Change Faceplate - White*
D3KIT-I	Wired Dimmer Color Change Faceplate - Ivory*
D3KIT-T	Wired Dimmer Color Change Faceplate - Light Almond*
D3KIT-B	Wired Dimmer Color Change Faceplate - Brown*
D3KIT-E	Wired Dimmer Color Change Faceplate - Black*
D3KIT-G	Wired Dimmer Color Change Faceplate - Gray*

*Use with Decora Smart Wi-Fi 3rd Gen D36HD



Catalog Number	Description
4-BUTTON COLOR CHANGE FACEPLATES	
DS4KT-1PW	4-Button Color Change Faceplate - White*
DS4KT-1PI	4-Button Color Change Faceplate - Ivory*
DS4KT-1PT	4-Button Color Change Faceplate - Light Almond*
DS4KT-1PE	4-Button Color Change Faceplate - Black*
DS4KT-1PB	4-Button Color Change Faceplate - Brown*
DS4KT-1PG	4-Button Color Change Faceplate - Gray*

*Use with Decora Smart Scene Controller Switch D2SCS





Catalog Number	Description
COLOR CHANGE FACEPLATE FOR OUTLETS	
DSRKT-1PW	Outlet Color Change Faceplate - White
DSRKT-1PI	Outlet Color Change Faceplate - Ivory
DSRKT-1PT	Outlet Color Change Faceplate - Light Almond
DSRKT-1PE	Outlet Color Change Faceplate - Black
DSRKT-1PB	Outlet Color Change Faceplate - Brown
DSRKT-1PG	Outlet Color Change Faceplate - Gray



Catalog Number	Description
4-BUTTON SONOS COLOR CHANGE FACEPLATES	
DS4KS-1PW	4-Button SONOS Color Change Faceplate - White*
DS4KS-1PI	4-Button SONOS Color Change Faceplate - Ivory*
DS4KS-1PT	4-Button SONOS Color Change Faceplate - Light Almond*
DS4KS-1PE	4-Button SONOS Color Change Faceplate - Black*
DS4KS-1PB	4-Button SONOS Color Change Faceplate - Brown*
DS4KS-1PG	4-Button SONOS Color Change Faceplate - Gray*

*Use with Decora Smart Scene Controller Switch D2SCS

  Decora Smart® **WiFi**



Leviton's Decora Motion Sensors Family

- Decora Motion Sensors offer flexible install and wiring options while using the latest in PIR technology to provide reliable motion-controlled lighting to any space without false trips; ideal for closets, bathrooms, garages, storage spaces and pantries, walk-in closets, laundry and utility rooms, basements
- Decora Humidity Sensors reduce moisture, mold, and mildew with advanced sensing that detects humidity to automatically activate ventilation and lessen condensation; never forget to turn exhaust fans on or off in bathrooms, basements, laundry area or spas



Catalog Number	Description	Sensor Type	Ratings	Voltage (VAC, Hz)	Replaces	Wired 3-Way	Neutral Required	Color Options
DOS02-0LW	2A Occupancy Sensor - White	Occupancy	150W LED/CFL, 250W Inc/Halogen, 250VA ELV, 200VA MLV, 2A Resistive	120V, 60Hz	IPS02	N	Optional	Y
DOS02-1LI	2A Occupancy Sensor- Ivory	Occupancy	150W LED/CFL, 250W Inc/Halogen, 250VA ELV, 200VA MLV, 2A Resistive	120V, 60Hz	IPS02	N	Optional	Y
DOS02-1LT	2A Occupancy Sensor - Light Almond	Occupancy	150W LED/CFL, 250W Inc/Halogen, 250VA ELV, 200VA MLV, 2A Resistive	120V, 60Hz	IPS02	N	Optional	Y
DOS05	5A Occupancy Sensor - W/I/LA	Occupancy	300W LED/CFL, 600W Inc/Halogen, 400VA MLV/ELV, 1/4HP Motor, 5A Resistive	120V, 60Hz	IPS05	Y	Optional	Y
DOS15	15A Occupancy Sensor - W/I/LA	Occupancy	600W LED/CFL, 1800W Inc, 1200VA MLV/ELV/ Fluorescent/Halogen, 1/2HP Motor, 15A Resistive	120V, 60Hz	IPS15	Y* and multi-sensor**	Y	Y
DVS02	2A Vacancy Sensor - White	Vacancy	150W LED/CFL, 250W Inc/Halogen, 250VA ELV, 200VA MLV, 2A Resistive	120V, 60Hz	IPV02	N	Optional	Y
DVS05	5A Vacancy Sensor - W/I/LA	Vacancy	300W LED/CFL, 600W Inc/Halogen, 400VA MLV/ELV, 1/4HP Motor, 5A Resistive	120V, 60Hz	IPV05	Y	Optional	Y
DVS15	15 Vacancy Sensor - W/I/LA	Vacancy	600W LED/CFL, 1800W Inc, 1200VA MLV/ELV/ Fluorescent/Halogen, 1/2HP Motor, 15A Resistive	120V, 60Hz	IPV15	Y* and multi-sensor**	Y	Y
DOD05	Combination Occupancy Sensor - White	Occupancy	Fan Load: 1/4HP Fan, 300W LED/CFL, 600W Inc/Halogen, 400VA MLV/ELV Light Load: 150W LED/CFL, 250W Inc/Halogen, 250VA ELV, 200VA MLV, 2A Resistive	120V, 60Hz	N/A	N	Optional	Y
DHS05-1LW	5A Humidity Sensor - White	Humidity	300W LED/CFL, 600W Inc/Halogen, 400VA ELV, 400VA MLV, 1/4HP Motor	120V, 60Hz	IPHS5	N	Optional	Y
DHS05-1LI	5A Humidity Sensor - Ivory	Humidity	300W LED/CFL, 600W Inc/Halogen, 400VA ELV, 400VA MLV, 1/4HP Motor	120V, 60Hz	IPHS5	N	Optional	Y
DHS05-1LT	5A Humidity Sensor - Light Almond	Humidity	300W LED/CFL, 600W Inc/Halogen, 400VA ELV, 400VA MLV 1/4HP Motor	120V, 60Hz	IPHS5	N	Optional	Y
DHD05	Combination Humidity Sensor - White	Humidity	Fan Load: 1/4HP Fan, 300W LED/CFL, 600W Inc/Halogen, 400VA MLV/ELV. Light Load: 150W LED/CFL, 250W Inc/Halogen, 250VA ELV, 200VA MLV, 2A Resistive	120V, 60Hz	N/A	N	Optional	Y

*With DD0SR
**With DOS15/
DVS15

Optional:
Neutral
or Ground
required

Accessories



Catalog Number	Description	Voltage (VAC, Hz)	Neutral Required	Color Options
WIRED COMPANIONS				
DD0SR-D	Wired Switch Companion (With Locator LED)	120/277V, 60Hz	Y	Y
DD0SR-1	Wired Switch Companion (Without Locator LED)	120V, 60Hz	N	Y



COLOR CHANGE FACEPLATES	
DOSKT-W	Sensor Color Change Faceplate - White
DOSKT-I	Sensor Color Change Faceplate - Ivory
DOSKT-T	Sensor Color Change Faceplate - Light Almond
DOSKT-G	Sensor Color Change Faceplate - Gray
DOSKT-E	Sensor Color Change Faceplate - Black
DOSKT-B	Sensor Color Change Faceplate - Brown
DHDKT-W	Combination Sensor Color Change Faceplate - White
DHDKT-I	Combination Sensor Color Change Faceplate - Ivory
DHDKT-T	Combination Sensor Color Change Faceplate - Light Almond
DHDKT-G	Combination Sensor Color Change Faceplate - Gray
DHDKT-E	Combination Sensor Color Change Faceplate - Black
DHDKT-B	Combination Sensor Color Change Faceplate - Brown



Leviton's Decora Timers Family

- Decora Countdown Timers feature easy to use button interface that provides timer control of lighting or ventilation, providing energy efficiency and cost savings. Countdown timers are ideal for closets, garages, or bathrooms; ensures lighting or exhaust fans are not left on
- Decora 24HR Programmable Timer is the ideal solution to enhance convenience, security, and energy efficiency by easily scheduling lights, ceiling fans, exhaust fans, small pumps, and more to turn on and off at specific times



Catalog Number	Description	Ratings	Voltage (VAC, Hz)	Replaces	Wired 3-Way	Neutral Required	Color Options
DT115	15 Minute Countdown Timer - White	600W LED/CFL, 1800W Inc/Halogen, 1200VA MLV/ELV/Fluorescent, 1/2HP/9.8A Fan/Motor, 15A Resistive	120V, 60Hz	LTB15	N	Optional	Y
DT130-1LW	30 Minute Countdown Timer - White	600W LED/CFL, 1800W Inc/Halogen, 1200VA MLV/ELV/Fluorescent, 1/2HP/9.8A Fan/Motor, 15A Resistive	120V, 60Hz	N/A	N	Optional	Y
DT130-1LT	30 Minute Countdown Timer - Light Almond	600W LED/CFL, 1800W Inc/Halogen, 1200VA MLV/ELV/Fluorescent, 1/2HP/9.8A Fan/Motor, 15A Resistive	120V, 60Hz	N/A	N	Optional	Y
DT160-1LW	60 Minute Countdown Timer - White	600W LED/CFL, 1800W Inc/Halogen, 1200VA MLV/ELV/Fluorescent, 1/2HP/9.8A Fan/Motor, 15A Resistive	120V, 60Hz	N/A	N	Optional	Y
DT160-1LT	60 Minute Countdown Timer - Light Almond	600W LED/CFL, 1800W Inc/Halogen, 1200VA MLV/ELV/Fluorescent, 1/2HP/9.8A Fan/Motor, 15A Resistive	120V, 60Hz	N/A	N	Optional	Y
DT102	2 Hour Countdown Timer - White	600W LED/CFL, 1800W Inc/Halogen, 1200VA MLV/ELV/Fluorescent, 1/2HP/9.8A Fan/Motor, 15A Resistive	120V, 60Hz	N/A	N	Optional	Y
DT104	4 Hour Countdown Timer - White	600W LED/CFL, 1800W Inc/Halogen, 1200VA MLV/ELV/Fluorescent, 1/2HP/9.8A Fan/Motor, 15A Resistive	120V, 60Hz	N/A	N	Optional	Y
DT112	12 Hour Countdown Timer - White	600W LED/CFL, 1800W Inc/Halogen, 1200VA MLV/ELV/Fluorescent, 1/2HP/9.8A Fan/Motor, 15A Resistive	120V, 60Hz	N/A	N	Optional	Y
DT230	30 Minute Countdown Timer - White	600W LED/CFL, 1800W Inc/Halogen, 1200VA MLV/ELV/Fluorescent, 1HP/16A Fan/Motor, 20A Resistive/16A Inductive	120V, 60Hz	LTB30	Y* and multi-timer**	Y	Y
DT260	60 Minute Countdown Timer - White	600W LED/CFL, 1800W Inc/Halogen, 1200VA MLV/ELV/Fluorescent, 1HP/16A Fan/Motor, 20A Resistive/16A Inductive	120V, 60Hz	LTB60	Y* and multi-timer**	Y	Y
DT202	2 Hour Countdown Timer - White	600W LED/CFL, 1800W Inc/Halogen, 1200VA MLV/ELV/Fluorescent, 1HP/16A Fan/Motor, 20A Resistive/16A Inductive	120V, 60Hz	LTB02	Y* and multi-timer**	Y	Y
DT204	4 Hour Countdown Timer - White	600W LED/CFL, 1800W Inc/Halogen, 1200VA MLV/ELV/Fluorescent, 1HP/16A Fan/Motor, 20A Resistive/16A Inductive	120V, 60Hz	N/A	Y* and multi-timer**	Y	Y
DT212	12 Hour Countdown Timer - White	600W LED/CFL, 1800W Inc/Halogen, 1200VA MLV/ELV/Fluorescent, 1HP/16A Fan/Motor, 20A Resistive/16A Inductive	120V, 60Hz	LTB12	Y* and multi-timer**	Y	Y
VPT24-1CW	24 Hour Programmable Timer - White	600W LED/CFL, 1800W Inc/Halogen, 1HP Fan/Motor, 15A Resistive/Inductive	120V, 60Hz	VPT24-1PZ/16Z/16W	Y***	Y	Y

*With DD0SR
 **With DT230/
 DT260/DT202/
 DT204/DT212
 ***Standard
 3-way switch

Optional:
 Neutral
 or Ground
 required

Accessories



Catalog Number	Description	Voltage (VAC, Hz)	Neutral Required	Color Options
WIRED COMPANIONS				
DD0SR-D	Wired Switch Companion (With Locator LED)	120/277V, 60Hz	Y	Y
DD0SR-1	Wired Switch Companion (Without Locator LED)	120V, 60Hz	N	Y



Catalog Number	Description
COLOR CHANGE FACEPLATE	
DTKIT-W	Timer Color Change Faceplate - White
DTKIT-I	Timer Color Change Faceplate - Ivory
DTKIT-T	Timer Color Change Faceplate - Light Almond
DTKIT-G	Timer Color Change Faceplate - Gray
DTKIT-E	Timer Color Change Faceplate - Black
DTKIT-B	Timer Color Change Faceplate - Brown



Catalog Number	Description
COLOR CHANGE FACEPLATE	
VPTKT-W	24 Hour Timer Color Change Faceplate - White
VPTKT-I	24 Hour Timer Color Change Faceplate - Ivory
VPTKT-T	24 Hour Timer Color Change Faceplate - Light Almond
VPTKT-G	24 Hour Timer Color Change Faceplate - Gray
VPTKT-E	24 Hour Timer Color Change Faceplate - Black

Leviton's Illumatech Family

- Ideal for meeting the needs of stand-alone commercial control application
- The portfolio includes 120/277V options for single-zone wired applications, multiple color options, and dimmers that do not require an additional power pack for switching
- Can be used to comply with IECC, ASHRAE 90.1 and California Title 24 energy code



Catalog Number	Description	Dimming Type	Ratings	Voltage (VAC, Hz)	Wired 3-Way*	Neutral Required	Color Options
IPL06-10Z	IllumaTech Dimmer - White/Ivory/ Light Almond - Non Lighted	Forward Phase TRIAC	150W LED/CFL, 600W Inc	120V, 60Hz	Y	N	Y***
IPE04-1LZ	IllumaTech ELV Dimmer - White/Ivory/ Light Almond - Lighted	Reverse Phase MOSFET	150W LED/CFL, 400W Inc, 400VA ELV	120V, 60Hz	Y	Y	Y**
IP710-F0W	IllumaTech Dimmer Switch for 0-10V LED, Mark 7 Fluorescent Ballasts	0-10V	10A LED 60Hz*, 120VAC/277VAC 1200VA Electronic Ballast 120VAC 1500VA Electronic Ballast 277VAC 50mA DC max sink current for 0-10V control	120/277 VAC, 50/60Hz	Y	N	Y***
IP710-FLW	IllumaTech Lighted Dimmer Switch for 0-10V LED, Mark 7 Fluorescent Ballasts	0-10V	10A LED 60Hz*, 120VAC/277VAC 1200VA Electronic Ballast 120VAC 1500VA Electronic Ballast 277VAC 50mA DC max sink current for 0-10V control	120/277 VAC, 50/60Hz	Y	N	Y**
IP710-LFZ	IllumaTech 0-10V Dimmer - White/Ivory/ Light Almond - Non Lighted - USMCA Compliant	0-10V	10A LED 60Hz*, 120VAC/277VAC 1200VA Electronic Ballast 120VAC 1500VA Electronic Ballast 277VAC	120/277V, 60Hz	Y	N	Y***
IPF01-1LZ	IllumaTech Fan Speed Control, 1.5A	N/A	1.5A Ceiling Fan	120V, 60 Hz	Y	N	Y**
IPF05-1LZ	IllumaTech Fan Speed Control, 5A	N/A	5A Ceiling Fan	120V, 60 Hz	Y	N	Y**
RTF01-10Z	IllumaTech Rotary 4-Speed Fan Control, 1.5A, White/Ivory/Light Almond	N/A	1.5A Ceiling Fan	120V, 60 Hz	N	N	N
RTF01-10W	IllumaTech Rotary 4-Speed Fan Control, 1.5A, White	N/A	1.5A Ceiling Fan	120V, 60 Hz	N	N	N
RTF01-10I	IllumaTech Rotary 4-Speed Fan Control, 1.5A, Ivory	N/A	1.5A Ceiling Fan	120V, 60 Hz	N	N	N

*Supports 50Hz, requires derating

*Standard 3-way switch

Accessories



Catalog Number	Description
LIGHTED COLOR CHANGE FACEPLATES**	
IPKIT-0W	IllumaTech Color Change Faceplate - White
IPKIT-0I	IllumaTech Color Change Faceplate - Ivory
IPKIT-0T	IllumaTech Color Change Faceplate - Light Almond
IPKIT-0G	IllumaTech Color Change Faceplate - Gray
IPKIT-0E	IllumaTech Color Change Faceplate - Black
IPKIT-0B	IllumaTech Color Change Faceplate - Brown
IPKIT-0R	IllumaTech Color Change Faceplate - Red



Catalog Number	Description
NON-LIGHTED COLOR CHANGE FACEPLATES***	
IPKIT-NW	IllumaTech Color Change Faceplate - White
IPKIT-NI	IllumaTech Color Change Faceplate - Ivory
IPKIT-NT	IllumaTech Color Change Faceplate - Light Almond
IPKIT-NG	IllumaTech Color Change Faceplate - Gray
IPKIT-NE	IllumaTech Color Change Faceplate - Black
IPKIT-NB	IllumaTech Color Change Faceplate - Brown
IPKIT-NR	IllumaTech Color Change Faceplate - Red



Catalog Number	Description
LIGHTED COLOR CHANGE FACEPLATES FOR ILLUMATECH FAN CONTROLLERS	
IPQFK-W	IllumaTech Fan Control Color Change Faceplate - White
IPQFK-I	IllumaTech Fan Control Color Change Faceplate - Ivory
IPQFK-T	IllumaTech Fan Control Color Change Faceplate - Light Almond
IPQFK-G	IllumaTech Fan Control Color Change Faceplate - Gray
IPQFK-E	IllumaTech Fan Control Color Change Faceplate - Black
IPQFK-B	IllumaTech Fan Control Color Change Faceplate - Brown



Rotary

Toggle Slide

SureSlide

Decora Slide

Decora Digital

Decora Smart



Leviton Manufacturing Co., Inc.

201 N Service Rd, Melville, NY 11747

Telephone: 1-800-323-8920 • Tech Line: 1-800-824-3005 (M-F 8AM-10PM EST, Sat 9AM-7PM EST)

Visit our Website at: leviton.com

© 2026 Leviton Manufacturing Co., Inc. All rights reserved. Specifications subject to change without notice.

26-R-0094-A-V4 081026