



The Leviton Load Center

The Future Made Current



NEMA 1 - Indoor, Order Cover & Door Assembly separately

| Amp Rating | # of Spaces/Circuits | Load Center Catalog Number | | Flush/Surface Mount Cover & Door Assembly | |
|---------------------------------------|----------------------|----------------------------|----------|---|-------------------------|
| | | Catalog Number | Replaces | Standard | with Observation Window |
| Main Breaker Factory Installed | | | | | |
| 100 | 20 | LP210-BPD | LP210-MB | LDC20 | LDC20-W |
| 125 | | LP212-BPD | LP212-MB | | |
| 150 | | LP215-BPD | LP215-MB | | |
| 200 | | LP220-BPD | LP220-MB | | |
| 100 | 30 | LP310-BPD | LP310-MB | LDC30 | LDC30-W |
| 125 | | LP312-BPD | LP312-MB | | |
| 150 | | LP315-BPD | LP315-MB | | |
| 200 | | LP320-BPD | LP320-MB | | |
| 150 | 42 | LP415-BPD | LP415-MB | LDC42 | LDC42-W |
| 200 | | LP420-BPD | LP420-MB | | |
| 225 | | LP422-BPD | LP422-MB | | |
| 200 | 66 | LP620-BPD | LP620-MB | LDC66 | LDC66-W |
| 225 | | LP622-BPD | LP622-MB | | |
| Main Lugs Only | | | | | |
| 225 | 20 | LP222-LPD | LP212-ML | LDC20 | LDC20-W |
| | 30 | LP322-LPD | LP320-ML | LDC30 | LDC30-W |
| | 42 | LP422-LPD | LP422-ML | LDC42 | LDC42-W |
| | 66 | LP622-LPD | LP622-1L | LDC66 | LDC66-W |



NEMA 3R - Outdoor

| Amp Rating | # of Spaces/Circuits | Catalog Number | Replaces |
|---------------------------------------|----------------------|----------------|----------|
| Main Breaker Factory Installed | | | |
| 100 | 20 | LR210-BDD | LP210-3B |
| 125 | | LR212-BDD | LP212-3B |
| 150 | | LR215-BDD | LP215-3B |
| 200 | | LR220-BDD | LP220-3B |
| 125 | 30 | LR312-BDD | LP312-3B |
| 150 | | LR315-BDD | LP315-3B |
| 200 | | LR320-BDD | LP320-3B |
| 150 | 42 | LR415-BDD | LP415-3B |
| 200 | | LR420-BDD | LP420-3B |
| 225 | | LR422-BDD | LP422-3B |
| Main Lugs Only | | | |
| 225 | 20 | LR222-LDD | LP212-3L |
| | 30 | LR322-LDD | LP320-3L |
| | 42 | LR422-LDD | LP422-3L |



Meter Main, UG/OH Service Entrance with Distribution Section and Feed-Through Lugs

| Amp Rating | # of Spaces/Circuits | Catalog Number | Replaces | Bypass | Cover |
|------------|----------------------|----------------|------------|------------------------------|-----------|
| 150 | 8 | LS815-BTD* | LP815-TMC* | None | Ringless |
| 200 | | LS820-BTD* | LP820-TMC* | None | Ringless |
| 150 | | LS815-BHD | LP815-HMC | Horn | Ringless |
| 200 | | LS820-BHD | LP820-HMC | Horn | Ringless |
| 150 | | LS815-BLD | LP815-LMC | Lever | Ringless |
| 200 | | LS820-BLD | LP820-LMC | Lever | Ringless |
| 150 | | LS815-B5D | LP815-5MC | Lever with 5th Jaw Installed | Ringless |
| 200 | | LS820-B5D | LP820-5MC | Lever with 5th Jaw Installed | Ringless |
| 150 | | LS815-BRD | LP815-RMC | None | Ring Type |
| 200 | | LS820-BRD | LP820-RMC | None | Ring Type |

*Includes internal trough to enable branch wiring through top of enclosure
All panels have a 225A bus rating and are solar compatible



Meter-Load Center Combination, All-in-one, Surface mount, UG Service Entrance, EUSERC

| Amp Rating | # of Spaces | Catalog Number | Replaces | Bypass | Cover |
|------------|-------------|----------------|----------|--------|-----------|
| 100 | 30 | LJ310-BED | LP310-MC | None | Ring Type |
| 125 | | LJ312-BED | LP312-MC | | |
| 150 | | LJ315-BED | LP315-MC | | |
| 200 | | LJ320-BED | LP320-MC | | |
| 200 | 42 | LJ420-BED | LP420-MC | | |
| 225 | | LJ422-BED | LP422-MC | | |

All panels have a 225A bus rating and are solar compatible




Meter-Load Center Combination, All-in-one, Semi-flush mount, UG/OH* Service Entrance, EUSERC

| Amp Rating | # Spaces/ circuits | Catalog Number | Replaces | Bypass | Cover |
|---------------------------------------|-----------------------|----------------|-----------|--------|-----------|
| Main Breaker Factory Installed | | | | | |
| 100 | 12 | LG110-BED | N/A | None | Ring Type |
| 125 | | LG112-BED | LP112-SR | | |
| 200 | | LG120-BED | LP120-SR | | |
| 100 | 30 | LG310-BED | N/A | | |
| 125 | | LG312-BED | LP312-SR | | |
| 200 | | LG320-BED | LP320-SR | | |
| 200 | 40 | LG420-BED | LP420-SR | | |
| 225 | | LG422-BED | LP422-SR | | |
| Main Lugs Only** | | | | | |
| 225 | 12 | LG122-LED | LP120-SRL | None | Ring Type |

*Overhead feed requires Overhead Tunnel Kit accessory

All panels have a 225A bus rating and are solar ready

**Requires LMBXX-T Main Breaker Conversion Kit for field installed main breaker

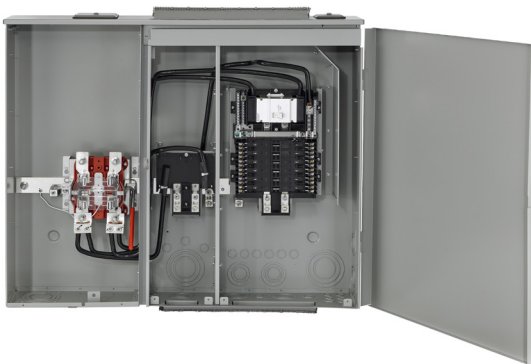

Class 320 Meter Main, UG/OH Service Entrance with Distribution Section and Feed-Through Lugs

| Amp Rating | # of Spaces/Circuits | Catalog Number | Bypass | Cover |
|------------|----------------------|----------------|--------|----------|
| 300 | 12 | LS130-S5D* | Lever | Ringless |
| 400 | 12 | LS140-S5D* | Lever | Ringless |

*LS130-S5D comes with (1) 150A main circuit breaker factory installed and LS140-S5D comes with (1) 200A main circuit breaker factory installed feeding 12-space distribution section with feed-through lugs

*Secondary main circuit breaker sold separately

* Meter socket supply connections include 3/8" mounting studs for utility or customer supplied mechanical lugs (See Leviton Part # LL260) or compression lugs per local utility requirements

MAIN CIRCUIT BREAKERS | 120/240 VAC, 22kA short-circuit rating



Main Breakers

| Amp Rating | Catalog Number | Replaces |
|------------|----------------|----------|
| 100 | LM100-T | LM100 |
| 125 | LM125-T | LM125 |
| 150 | LM150-T | LM150 |
| 175 | LM175-T | N/A |
| 200 | LM200-T | LM200 |
| 225 | LM225-T | LM225 |



MB Conversion Kit for Semi-flush Mount Meter-Load Center Combinations

| Amp Rating | Catalog Number | Replaces |
|------------|----------------|----------|
| 100 | LMB10-T | LMB10 |
| 125 | LMB12-T | LMB12 |
| 150 | LMB15-T | LMB15 |
| 175 | LMB17-T | N/A |
| 200 | LMB20-T | LMB20 |
| 225 | LMB22-T | LMB22 |

2nd Gen Smart Circuit Breakers with Remote Control Functionality

10kA short-circuit rating*

2nd Gen Smart Standard

| Amp Rating | 1-Pole 120V | 2-Pole 120/208V 120/240V |
|------------|-------------|--------------------------|
| 15 | LB115-ST | LB215-ST |
| 20 | LB120-ST | LB220-ST |
| 25 | LB125-ST | LB225-ST |
| 30 | LB130-ST | LB230-ST |
| 35 | - | LB235-ST |
| 40 | - | LB240-ST |
| 45 | - | LB245-ST |
| 50 | - | LB250-ST |
| 60 | - | LB260-ST |

2nd Gen Smart AFCI

| Amp Rating | 1-Pole 120V |
|------------|-------------|
| 15 | LB115-AST |
| 20 | LB120-AST |

2nd Gen Smart GFCI - 5 mA Ground-Fault Protection of Personnel


| Amp Rating | 1-Pole 120V | 2-Pole 120/208V 120/240V |
|------------|-------------|--------------------------|
| 15 | LB115-GST | LB215-GST |
| 20 | LB120-GST | LB220-GST |
| 25 | LB125-GST | LB225-GST |
| 30 | LB130-GST | LB230-GST |
| 35 | - | LB235-GST |
| 40 | - | LB240-GST |
| 45 | - | LB245-GST |
| 50 | - | LB250-GST |
| 60 | - | LB260-GST |

2nd Gen Smart AFCI/GFCI - Dual Function

| Amp Rating | 1-Pole 120V |
|------------|-------------|
| 15 | LB115-DST |
| 20 | LB120-DST |

2nd Gen Smart GFPE - 30 mA Ground-Fault Protection of Equipment

| Amp Rating | 1-Pole 120V | 2-Pole 120/208V 120/240V |
|------------|-------------|--------------------------|
| 15 | LB115-EST | LB215-EST |
| 20 | LB120-EST | LB220-EST |
| 25 | LB125-EST | LB225-EST |
| 30 | LB130-EST | LB230-EST |
| 40 | - | LB240-EST |
| 50 | - | LB250-EST |
| 60 | - | LB260-EST |

 

| Catalog Number | Description |
|----------------|--|
| LWHEM-2 | Leviton Whole Home Energy Monitor with 1 pair of Current Transformers* |
| LSMMA | Additional Metering Accessory for LWHEM-2 |
| LSBMA | Metering Accessory for 2-Pole Branch Circuit Breakers |

*Each LWHEM-2 can support up to three pairs of LSMMA CTs

*Series Rated 22kA with Leviton Main Breaker; see Series Ratings Tables for additional Ratings

BRANCH CIRCUIT BREAKERS

10kA short-circuit rating*

Standard

| Amp Rating | 1-Pole 120V | 2-Pole 120/208V 120/240V |
|------------|-------------|--------------------------|
| 15 | LB115-T | LB215-T |
| 20 | LB120-T | LB220-T |
| 25 | LB125-T | LB225-T |
| 30 | LB130-T | LB230-T |
| 35 | - | LB235-T |
| 40 | - | LB240-T |
| 45 | - | LB245-T |
| 50 | - | LB250-T |
| 60 | - | LB260-T |
| 70 | - | LB270 |
| 80 | - | LB280 |
| 90 | - | LB290 |
| 100 | - | LB200 |
| 110 | - | LB211 |
| 125 | - | LB212 |

AFCI

| Amp Rating | 1-Pole 120V | 2-Pole 120V/240V |
|------------|-------------|------------------|
| 15 | LB115-AFT | LB215-AF |
| 20 | LB120-AFT | LB220-AF |

GFCI - 5 mA Ground-Fault Protection of Personnel

| Amp Rating | 1-Pole 120V | 2-Pole 120/208V 120/240V |
|------------|-------------|--------------------------|
| 15 | LB115-GFT | LB215-G |
| 20 | LB120-GFT | LB220-G |
| 25 | LB125-GFT | LB225-G |
| 30 | LB130-GFT | LB230-G |
| 40 | - | LB240-G |
| 50 | - | LB250-G |
| 60 | - | LB260-G |

GFPE - 30 mA Ground-Fault Protection of Equipment

| Amp Rating | 1-Pole 120V | 2-Pole 120V/240V |
|------------|-------------|------------------|
| 15 | LB115-EPT | LB215-EP |
| 20 | LB120-EPT | LB220-E |
| 25 | LB125-EPT | LB225-EP |
| 30 | LB130-EPT | LB230-EP |
| 40 | - | LB240-EP |
| 50 | - | LB250-EP |
| 60 | - | LB260-EP |

AFCI/GFCI - Dual Function

| Amp Rating | 1-Pole 120V |
|------------|-------------|
| 15 | LB115-DFT |
| 20 | LB120-DFT |

Surge Protection*

| Description | Catalog Number |
|---|----------------|
| Surge Protective Device and Two 1-Pole 15A Circuit Breakers, 120V | LSPD1-T |
| Surge Protective Device and Two 1-Pole 20A Circuit Breakers, 120V | LSPD2-T |

*Series Rated 22kA with Leviton Main Breaker; see Series Ratings Tables for additional Ratings

*Nominal Discharge Current Rating: 10kA

ACCESSORIES

Locking & Latching Devices



| Description | Catalog Number |
|---|----------------|
| Handle padlock device for branch circuit breakers | LBHPL |
| Handle padlock device for main circuit breakers | LMHPL |
| Door locking latch kit for indoor load centers | LDRLK |
| Door latch kit without lock for indoor load centers | LDRLA |

Lugs, Ground and Neutral Bar Kits



| Description | Catalog Number |
|---|----------------|
| Field-installable main lugs, 3 - 300 | LL630 |
| Ground lug, 6 - 2/0 | LLGND |
| Neutral lug, 6 - 300 | LLNLT |
| Phase/neutral load side lug, 14 - 4 (qty. 6) | LLPHN |
| Ground bar kit, 11 positions, 14 - 4 | LGBKT |
| Neutral bar kit, 14 - 1/0 | LNBKT |
| Field-Installable Neutral Feed-through lug, 4 - 2/0 | LL420 |
| Field-Installable Neutral Feed-through lug, 3 - 300 | LN330 |
| Feed-through lug accessory | LFTLA |
| Field-Installable Meter Socket Terminal Connectors, 2 - 600 | LL260 |

Outdoor & Meter Combination Load Center Accessories



| Description | Catalog Number |
|--|----------------|
| Conduit hub, 1" | LHUB1 |
| Conduit hub, 2" | LHB02 |
| Conduit hub, 2 1/2" | LHUB2 |
| Closing plate | LCLPT |
| 5th Jaw for standard meter sockets | L5JAW |
| 5th Jaw with neutral for lever bypass meter socket | L5JAW-N |
| Ground connector | LGDMC |
| Sealing ring | LRING |

Overhead Tunnel Kits: for Semi-flush Mount Meter-Load Center Combinations



| Description | Catalog Number |
|--------------------|----------------|
| For 12-space Panel | LOTK1 |
| For 30-space Panel | LOTK3 |
| For 40-space Panel | LOTK4 |

Miscellaneous



| Description | Catalog Number |
|---|----------------|
| Generator interlock kit | LITLK |
| Breaker Hold Down kit | LBHDK |
| Angle iron bracket for flush mount load centers | LBRKT |
| 20 Space Load Center Circuit Identification Sticker Pack for Standard Doors | LSTK2 |
| 30 Space Load Center Circuit Identification Sticker Pack for Standard Doors | LSTK3 |
| 42 Space Load Center Circuit Identification Sticker Pack for Standard Doors | LSTK4 |
| 66 Space Load Center Circuit Identification Sticker Pack for Standard Doors | LSTK6 |
| 20 Space Load Center Circuit Identification Sticker Pack for Window Doors | LSTK2-W |
| 30 Space Load Center Circuit Identification Sticker Pack for Window Doors | LSTK3-W |
| 42 Space Load Center Circuit Identification Sticker Pack for Window Doors | LSTK4-W |
| 66 Space Load Center Circuit Identification Sticker Pack for Window Doors | LSTK6-W |
| Filler Plates (qty. 10) | LFPLT |
| Terminal covers for main circuit breaker | LTCVR |
| Bonding strap kit | LPBSK |
| Cover screw kit (qty. 6) | LDCSK |
| GFCI-protected outlet labels, pack of 1000 | GFLBL-LBL |
| EMERGENCY DISCONNECT labels, pack of 10 | LDSCl |



Leviton Manufacturing Co., Inc.

Tech Line: 1-800-824-3005

Mon-Fri 8am-10pm EST, Saturday 9am-7pm EST, Sunday 9am-5pm EST

For 24/7 product support visit www.leviton.com/support

Visit our Website at: www.leviton.com/loadcenter

© 2025 Leviton Manufacturing Co., Inc. All rights reserved.
All trademarks are the property of their respective owners.

